


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® Sapphire Windows

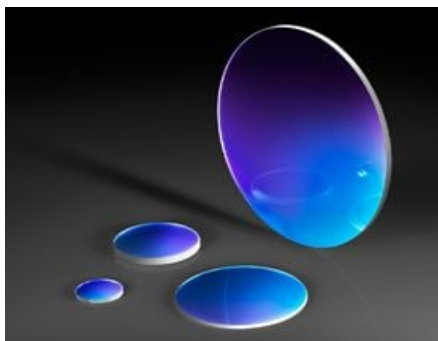

- Features Extreme Surface Hardness Chemical Resistance
- Transmits Wavelengths Ranging From UV to Mid-Infrared
- Thinner and Stronger than Standard Glass Windows
- Anti-Reflection Coating Options Covering 350 - 5000nm Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	≥90
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	1,900.00
Poisson's Ratio:	0.27	Young's Modulus (GPa):	435



Optical Properties

Abbe Number (v_d):	72.24	Axis Orientation:	Random
Birefringence (n_o-n_e):	0.008 for Visible Light Orthogonal to Optical Axis	Index of Refraction (n_d):	1.77
Substrate:	Sapphire (Al ₂ O ₃)	Surface Quality:	80-50


Material Properties

Coefficient of Thermal Expansion CTE (10⁻⁶/°C):	5.4 (Parallel to C-Axis) 4.3 (Perpendicular to C-Axis)	Density (g/cm³):	3.97
---	---	------------------------------------	------


Technical Information

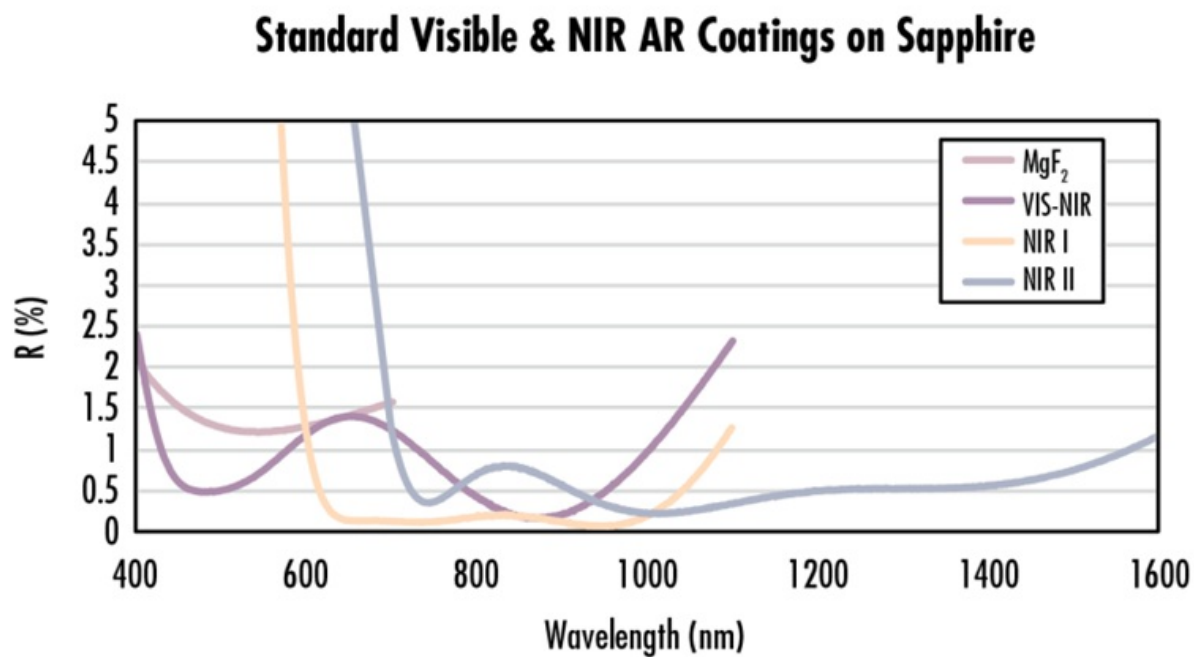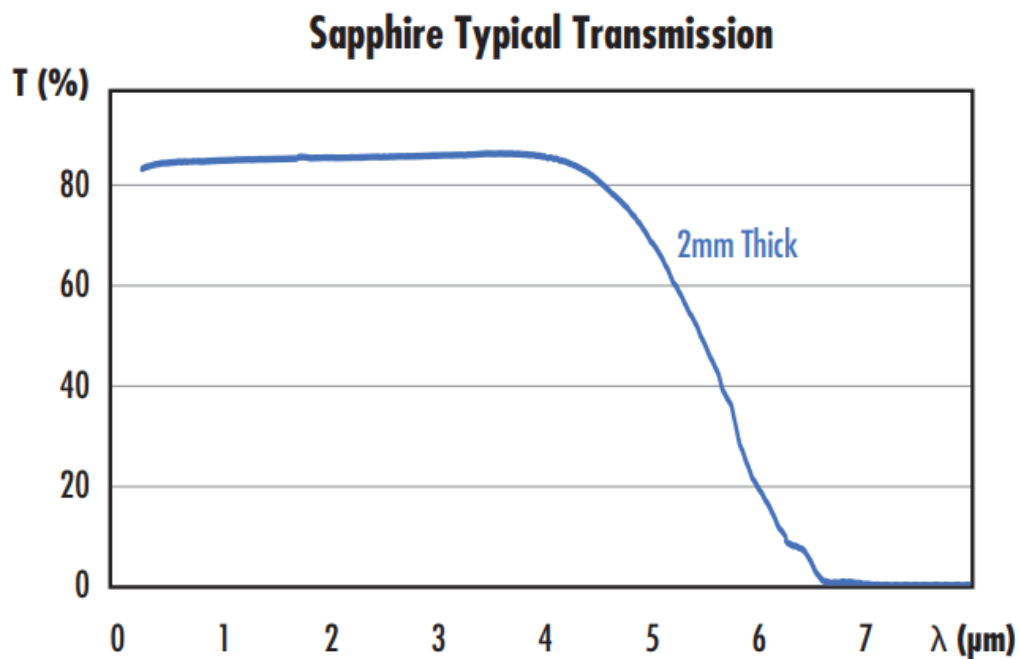

Infrared BBAR Coatings on Sapphire

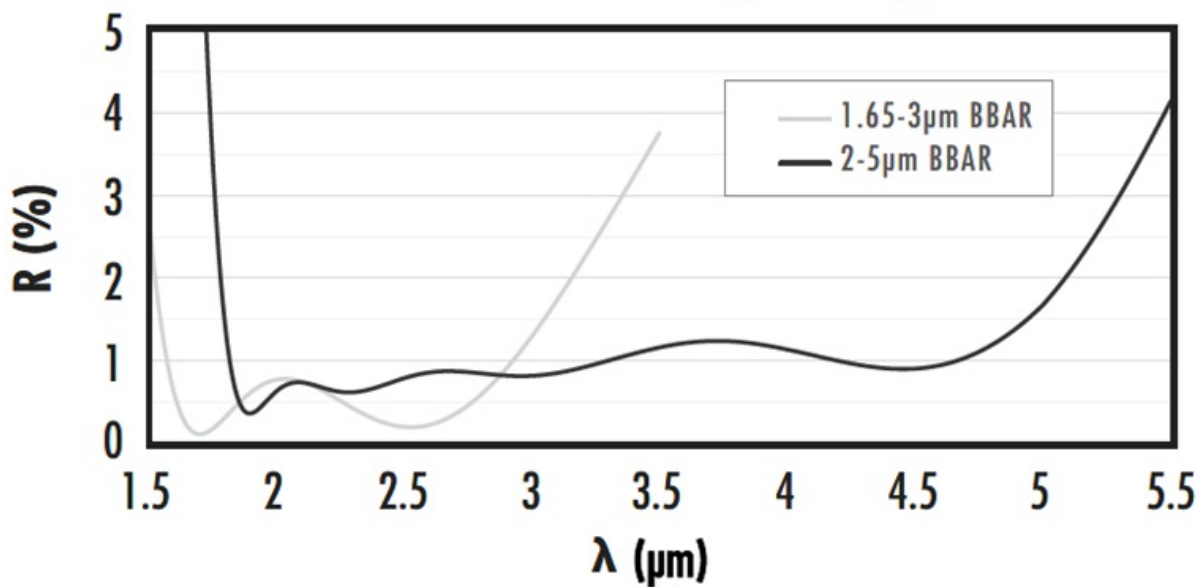

Infrared AR Coated Sapphire Windows 1mm Thickness

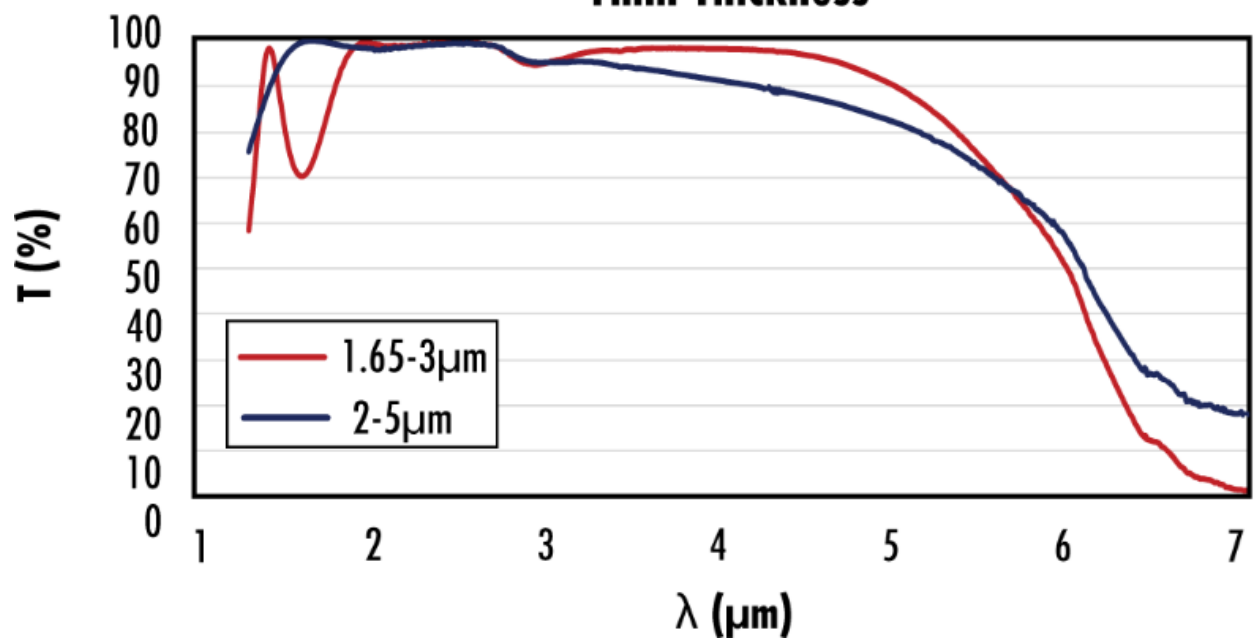

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
1.00	-	0.50	Uncoated	#17-216	€26,27 Volume Pricing	20+ In Stock
2.50	-	0.50	Uncoated	#43-627	€26,27 Volume Pricing	20+ In Stock
3.20	-	1.00	Uncoated	#17-217	€26,27 Volume Pricing	20+ In Stock
5.00	-	0.20	Uncoated	#71-217	€41,20 Volume Pricing	20+ In Stock
5.00	-	0.50	Uncoated	#17-218	€36,05 Volume Pricing	20+ In Stock
5.00	-	1.00	Uncoated	#43-365	€36,05 Volume Pricing	20+ In Stock
5.00	-	2.00	Uncoated	#25-376	€36,05 Volume Pricing	20+ In Stock
5.00	-	3.00	Uncoated	#25-377	€36,05 Volume Pricing	20+ In Stock
5.00	-	0.50	MgF ₂ (400-700nm)	#20-623	€53,56 Volume Pricing	7 In Stock
5.00	-	1.00	MgF ₂ (400-700nm)	#36-197	€53,56 Volume Pricing	9 In Stock
5.00	-	2.00	MgF ₂ (400-700nm)	#25-386	€53,56 Volume Pricing	3 In Stock
5.00	-	3.00	MgF ₂ (400-700nm)	#25-387	€53,56 Volume Pricing	1 In Stock
5.00	-	0.50	VIS-EXT (350-700nm)	#28-512	€59,23 Volume Pricing	7 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#28-513	€59,23 Volume Pricing	20+ In Stock

5.00	-	2.00	VIS-EXT (350-700nm)	#28-514	€59,23 Volume Pricing	5 In Stock
5.00	-	3.00	VIS-EXT (350-700nm)	#28-515	€59,23 Volume Pricing	10 In Stock
5.00	-	0.50	VIS-NIR (400-1000nm)	#20-741	€59,23 Volume Pricing	1 In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#36-577	€59,23 Volume Pricing	5 In Stock
5.00	-	2.00	VIS-NIR (400-1000nm)	#25-396	€59,23 Volume Pricing	1 In Stock
5.00	-	3.00	VIS-NIR (400-1000nm)	#25-397	€59,23 Volume Pricing	Contact Us
5.00	-	0.50	NIR I (600-1050nm)	#20-838	€59,23 Volume Pricing	Contact Us
5.00	-	1.00	NIR I (600-1050nm)	#36-477	€59,23 Volume Pricing	12 In Stock
5.00	-	2.00	NIR I (600-1050nm)	#25-406	€59,23 Volume Pricing	4 In Stock
5.00	-	3.00	NIR I (600-1050nm)	#25-407	€59,23 Volume Pricing	2 In Stock
5.00	-	0.50	NIR II (750-1550nm)	#20-904	€59,23 Volume Pricing	10 In Stock
5.00	-	1.00	NIR II (750-1550nm)	#36-562	€59,23 Volume Pricing	Contact Us
5.00	-	2.00	NIR II (750-1550nm)	#25-416	€59,23 Volume Pricing	9 In Stock
5.00	-	3.00	NIR II (750-1550nm)	#25-417	€59,23 Volume Pricing	2 In Stock

5.00	-	0.50	BBAR (1650-3000nm)	#20-974	€75,71 Volume Pricing	7 In Stock
5.00	-	1.00	BBAR (1650-3000nm)	#15-988	€75,71 Volume Pricing	20+ In Stock
5.00	-	2.00	BBAR (1650-3000nm)	#25-426	€75,71 Volume Pricing	4 In Stock
5.00	-	3.00	BBAR (1650-3000nm)	#25-427	€75,71 Volume Pricing	5 In Stock
5.00	-	0.50	BBAR (2000-5000nm)	#21-011	€75,71 Volume Pricing	5 In Stock
5.00	-	1.00	BBAR (2000-5000nm)	#16-000	€75,71 Volume Pricing	5 In Stock
5.00	-	2.00	BBAR (2000-5000nm)	#25-436	€75,71 Volume Pricing	4 In Stock
5.00	-	3.00	BBAR (2000-5000nm)	#25-437	€75,71 Volume Pricing	5 In Stock
6.35	-	0.20	Uncoated	#71-218	€41,20 Volume Pricing	20+ In Stock
6.35	-	0.50	Uncoated	#45-567	€36,05 Volume Pricing	20+ In Stock
6.35	-	1.00	Uncoated	#17-219	€36,05 Volume Pricing	20+ In Stock
6.35	-	2.00	Uncoated	#17-220	€36,05 Volume Pricing	20+ In Stock
6.35	-	0.50	MgF ₂ (400-700nm)	#39-231	€53,56 Volume Pricing	20+ In Stock
6.35	-	1.00	MgF ₂ (400-700nm)	#20-627	€53,56 Volume Pricing	1 In Stock
6.35	-	2.00	MgF ₂ (400-700nm)	#20-629	€53,56 Volume Pricing	2 In Stock

6.35	-	0.50	VIS-EXT (350-700nm)	#28-516	€59,23 Volume Pricing	14 In Stock
6.35	-	1.00	VIS-EXT (350-700nm)	#28-517	€59,23 Volume Pricing	14 In Stock
6.35	-	2.00	VIS-EXT (350-700nm)	#28-518	€59,23 Volume Pricing	5 In Stock
6.35	-	0.50	VIS-NIR (400-1000nm)	#39-246	€59,23 Volume Pricing	1 In Stock
6.35	-	1.00	VIS-NIR (400-1000nm)	#20-760	€59,23 Volume Pricing	Contact Us
6.35	-	2.00	VIS-NIR (400-1000nm)	#20-763	€59,23 Volume Pricing	2 In Stock
6.35	-	0.50	NIR I (600-1050nm)	#39-252	€59,23 Volume Pricing	5 In Stock
6.35	-	1.00	NIR I (600-1050nm)	#20-839	€59,23 Volume Pricing	Contact Us
6.35	-	2.00	NIR I (600-1050nm)	#20-841	€59,23 Volume Pricing	12 In Stock
6.35	-	0.50	NIR II (750-1550nm)	#39-262	€59,23 Volume Pricing	Contact Us
6.35	-	1.00	NIR II (750-1550nm)	#20-908	€59,23 Volume Pricing	Contact Us
6.35	-	2.00	NIR II (750-1550nm)	#20-913	€59,23 Volume Pricing	1 In Stock
6.35	-	0.50	BBAR (1650-3000nm)	#15-989	€75,71 Volume Pricing	11 In Stock
6.35	-	1.00	BBAR (1650-3000nm)	#20-976	€75,71 Volume Pricing	7 In Stock

6.35	-	2.00	BBAR (1650-3000nm)	#20-977	€75,71 Volume Pricing	5 In Stock
6.35	-	0.50	BBAR (2000-5000nm)	#16-001	€75,71 Volume Pricing	4 In Stock
6.35	-	1.00	BBAR (2000-5000nm)	#21-013	€75,71 Volume Pricing	2 In Stock
6.35	-	2.00	BBAR (2000-5000nm)	#21-015	€75,71 Volume Pricing	4 In Stock
7.50	-	0.40	Uncoated	#43-628	€36,05 Volume Pricing	20+ In Stock
9.50	-	0.50	Uncoated	#43-629	€36,05 Volume Pricing	20+ In Stock
10.00	-	0.20	Uncoated	#71-221	€49,44 Volume Pricing	20+ In Stock
10.00	-	0.50	Uncoated	#17-221	€49,44 Volume Pricing	20+ In Stock
10.00	-	1.00	Uncoated	#43-366	€49,44 Volume Pricing	20+ In Stock
10.00	-	2.00	Uncoated	#25-378	€49,44 Volume Pricing	9 In Stock
10.00	-	3.00	Uncoated	#25-379	€49,44 Volume Pricing	20+ In Stock
10.00	-	0.50	MgF ₂ (400-700nm)	#20-633	€66,95 Volume Pricing	3 In Stock
10.00	-	1.00	MgF ₂ (400-700nm)	#36-201	€66,95 Volume Pricing	9 In Stock
10.00	-	2.00	MgF ₂ (400-700nm)	#25-388	€66,95 Volume Pricing	4 In Stock
10.00	-	3.00	MgF ₂ (400-700nm)	#25-389	€66,95 Volume Pricing	1 In Stock
10.00	-	0.50	VIS-EXT (350-700nm)	#28-519	€72,62 Volume Pricing	8 In Stock

10.00	-	1.00	VIS-EXT (350-700nm)	#28-553	€72,62 Volume Pricing	1 In Stock
10.00	-	2.00	VIS-EXT (350-700nm)	#28-554	€72,62 Volume Pricing	4 In Stock
10.00	-	3.00	VIS-EXT (350-700nm)	#28-555	€72,62 Volume Pricing	12 In Stock
10.00	-	0.50	VIS-NIR (400-1000nm)	#20-765	€72,62 Volume Pricing	4 In Stock
10.00	-	1.00	VIS-NIR (400-1000nm)	#36-578	€72,62 Volume Pricing	3 In Stock
10.00	-	0.50	NIR I (600-1050nm)	#20-848	€72,62 Volume Pricing	2 In Stock
10.00	-	1.00	NIR I (600-1050nm)	#36-487	€72,62 Volume Pricing	6 In Stock
10.00	-	0.50	NIR II (750-1550nm)	#20-914	€72,62 Volume Pricing	Contact Us
10.00	-	1.00	NIR II (750-1550nm)	#36-566	€72,62 Volume Pricing	8 In Stock
10.00	-	2.00	VIS-NIR (400-1000nm)	#25-398	€72,62 Volume Pricing	2 In Stock
10.00	-	3.00	VIS-NIR (400-1000nm)	#25-399	€72,62 Volume Pricing	11 In Stock
10.00	-	2.00	NIR I (600-1050nm)	#25-408	€72,62 Volume Pricing	5 In Stock
10.00	-	3.00	NIR I (600-1050nm)	#25-409	€72,62 Volume Pricing	16 In Stock
10.00	-	2.00	NIR II (750-1550nm)	#25-418	€72,62 Volume Pricing	20+ In Stock

10.00	-	3.00	NIR II (750-1550nm)	#25-419	€72,62 Volume Pricing	3 In Stock
10.00	-	0.50	BBAR (1650-3000nm)	#20-981	€89,10 Volume Pricing	3 In Stock
10.00	-	1.00	BBAR (1650-3000nm)	#15-990	€89,10 Volume Pricing	Contact Us
10.00	-	2.00	BBAR (1650-3000nm)	#25-428	€89,10 Volume Pricing	2 In Stock
10.00	-	3.00	BBAR (1650-3000nm)	#25-429	€89,10 Volume Pricing	4 In Stock
10.00	-	0.50	BBAR (2000-5000nm)	#21-016	€89,10 Volume Pricing	Contact Us
10.00	-	1.00	BBAR (2000-5000nm)	#16-002	€89,10 Volume Pricing	Contact Us
10.00	-	2.00	BBAR (2000-5000nm)	#25-438	€89,10 Volume Pricing	5 In Stock
10.00	-	3.00	BBAR (2000-5000nm)	#25-439	€89,10 Volume Pricing	5 In Stock
12.50	-	1.00	VIS-EXT (350-700nm)	#28-556	€75,19 Volume Pricing	2 In Stock
12.50	-	1.00	Uncoated	#36-252	€52,02 Volume Pricing	20+ In Stock
12.50	-	1.00	MgF ₂ (400-700nm)	#36-202	€69,53 Volume Pricing	9 In Stock
12.50	-	1.00	VIS-NIR (400-1000nm)	#36-579	€75,19 Volume Pricing	20+ In Stock
12.50	-	1.00	NIR I (600-1050nm)	#36-488	€75,19 Volume Pricing	17 In Stock

12.50	-	1.00	NIR II (750-1550nm)	#36-567	€75,19 Volume Pricing	9 In Stock
12.50	-	1.00	BBAR (1650-3000nm)	#15-991	€91,67 Volume Pricing	Contact Us
12.50	-	1.00	BBAR (2000-5000nm)	#16-003	€91,67 Volume Pricing	Contact Us
-	12.50 x 12.50	1.00	Uncoated	#39-228	€52,02 Volume Pricing	20+ In Stock
12.70	-	0.20	Uncoated	#71-224	€53,56 Volume Pricing	20+ In Stock
12.70	-	0.50	Uncoated	#17-222	€53,56 Volume Pricing	20+ In Stock
12.70	-	1.00	Uncoated	#17-223	€53,56 Volume Pricing	20+ In Stock
12.70	-	2.00	Uncoated	#17-224	€53,56 Volume Pricing	20+ In Stock
12.70	-	3.18	Uncoated	#68-157	€53,56 Volume Pricing	20+ In Stock
12.70	-	0.50	MgF ₂ (400-700nm)	#20-634	€71,59 Volume Pricing	6 In Stock
12.70	-	1.00	MgF ₂ (400-700nm)	#20-635	€71,59 Volume Pricing	1 In Stock
12.70	-	2.00	MgF ₂ (400-700nm)	#20-638	€71,59 Volume Pricing	6 In Stock
12.70	-	3.18	MgF ₂ (400-700nm)	#39-232	€71,59 Volume Pricing	3 In Stock
12.70	-	1.00	VIS-EXT (350-700nm)	#28-558	€76,74 Volume Pricing	11 In Stock
12.70	-	2.00	VIS-EXT (350-700nm)	#28-559	€76,74 Volume Pricing	14 In Stock
12.70	-	3.18	VIS-EXT (350-700nm)	#28-560	€76,74 Volume Pricing	14 In Stock

12.70	-	0.50	VIS-NIR (400-1000nm)	#20-766	€76,74 Volume Pricing	20+ In Stock
12.70	-	1.00	VIS-NIR (400-1000nm)	#20-771	€76,74 Volume Pricing	5 In Stock
12.70	-	2.00	VIS-NIR (400-1000nm)	#20-788	€76,74 Volume Pricing	5 In Stock
12.70	-	3.18	VIS-NIR (400-1000nm)	#39-247	€76,74 Volume Pricing	20+ In Stock
12.70	-	0.50	NIR I (600-1050nm)	#20-850	€76,74 Volume Pricing	5 In Stock
12.70	-	1.00	NIR I (600-1050nm)	#20-857	€76,74 Volume Pricing	15 In Stock
12.70	-	2.00	NIR I (600-1050nm)	#20-859	€76,74 Volume Pricing	Contact Us
12.70	-	3.18	NIR I (600-1050nm)	#39-253	€76,74 Volume Pricing	1 In Stock
12.70	-	0.50	NIR II (750-1550nm)	#20-918	€76,74 Volume Pricing	6 In Stock
12.70	-	1.00	NIR II (750-1550nm)	#20-926	€76,74 Volume Pricing	12 In Stock
12.70	-	2.00	NIR II (750-1550nm)	#20-927	€76,74 Volume Pricing	6 In Stock
12.70	-	3.18	NIR II (750-1550nm)	#39-263	€76,74 Volume Pricing	11 In Stock
12.70	-	0.50	BBAR (1650-3000nm)	#21-000	€93,22 Volume Pricing	5 In Stock
12.70	-	0.50	VIS-EXT (350-700nm)	#28-557	€76,74 Volume Pricing	5 In Stock

12.70	-	1.00	BBAR (1650-3000nm)	#21-001	€93,22 Volume Pricing	Contact Us
12.70	-	2.00	BBAR (1650-3000nm)	#21-002	€93,22 Volume Pricing	5 In Stock
12.70	-	3.18	BBAR (1650-3000nm)	#15-992	€93,22 Volume Pricing	1 In Stock
12.70	-	0.50	BBAR (2000-5000nm)	#21-017	€93,22 Volume Pricing	10 In Stock
12.70	-	1.00	BBAR (2000-5000nm)	#21-018	€93,22 Volume Pricing	Contact Us
12.70	-	2.00	BBAR (2000-5000nm)	#21-019	€93,22 Volume Pricing	13 In Stock
12.70	-	3.18	BBAR (2000-5000nm)	#16-004	€93,22 Volume Pricing	20+ In Stock
12.75	-	1.00	Uncoated	#43-631	€53,56 Volume Pricing	20+ In Stock
13.00	-	0.50	Uncoated	#43-632	€53,56 Volume Pricing	20+ In Stock
15.00	-	0.20	Uncoated	#71-225	€67,98 Volume Pricing	10 In Stock
15.00	-	0.50	Uncoated	#17-225	€67,98 Volume Pricing	14 In Stock
15.00	-	1.00	Uncoated	#17-226	€67,98 Volume Pricing	20+ In Stock
15.00	-	2.00	Uncoated	#43-367	€67,98 Volume Pricing	20+ In Stock
15.00	-	0.50	MgF ₂ (400-700nm)	#20-642	€85,49 Volume Pricing	5 In Stock
15.00	-	1.00	MgF ₂ (400-700nm)	#20-647	€85,49 Volume Pricing	3 In Stock
15.00	-	2.00	MgF ₂ (400-700nm)	#36-206	€85,49 Volume Pricing	8 In Stock

15.00	-	0.50	VIS-EXT (350-700nm)	#28-561	€91,16 Volume Pricing	5 In Stock
15.00	-	1.00	VIS-EXT (350-700nm)	#28-562	€91,16 Volume Pricing	2 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#28-563	€91,16 Volume Pricing	Contact Us
15.00	-	0.50	VIS-NIR (400-1000nm)	#20-792	€91,16 Volume Pricing	9 In Stock
15.00	-	1.00	VIS-NIR (400-1000nm)	#20-793	€91,16 Volume Pricing	20+ In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#36-580	€91,16 Volume Pricing	7 In Stock
15.00	-	0.50	NIR I (600-1050nm)	#20-867	€91,16 Volume Pricing	5 In Stock
15.00	-	1.00	NIR I (600-1050nm)	#20-870	€91,16 Volume Pricing	9 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#36-492	€91,16 Volume Pricing	Contact Us
15.00	-	0.50	NIR II (750-1550nm)	#20-936	€91,16 Volume Pricing	4 In Stock
15.00	-	1.00	NIR II (750-1550nm)	#20-939	€91,16 Volume Pricing	4 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#36-571	€91,16 Volume Pricing	20+ In Stock
15.00	-	0.50	BBAR (1650-3000nm)	#21-003	€108,15 Volume Pricing	6 In Stock
15.00	-	1.00	BBAR (1650-3000nm)	#21-004	€108,15 Volume Pricing	3 In Stock

15.00	-	2.00	BBAR (1650-3000nm)	#15-993	€108,15 Volume Pricing	4 In Stock
15.00	-	0.50	BBAR (2000-5000nm)	#21-020	€108,15 Volume Pricing	5 In Stock
15.00	-	1.00	BBAR (2000-5000nm)	#21-021	€108,15 Volume Pricing	12 In Stock
15.00	-	2.00	BBAR (2000-5000nm)	#16-005	€108,15 Volume Pricing	20+ In Stock
17.25	-	1.00	Uncoated	#71-226	€67,98 Volume Pricing	11 In Stock
17.25	-	2.00	Uncoated	#43-633	€67,98 Volume Pricing	20+ In Stock
20.00	-	0.20	Uncoated	#71-227	€84,46 Volume Pricing	20+ In Stock
20.00	-	0.50	Uncoated	#17-227	€84,46 Volume Pricing	20+ In Stock
20.00	-	1.00	Uncoated	#17-228	€84,46 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#43-368	€84,46 Volume Pricing	20+ In Stock
20.00	-	3.00	Uncoated	#25-380	€84,46 Volume Pricing	20+ In Stock
20.00	-	0.50	MgF ₂ (400-700nm)	#20-660	€101,97 Volume Pricing	5 In Stock
20.00	-	1.00	MgF ₂ (400-700nm)	#20-663	€101,97 Volume Pricing	6 In Stock
20.00	-	2.00	MgF ₂ (400-700nm)	#36-457	€101,97 Volume Pricing	20+ In Stock
20.00	-	3.00	MgF ₂ (400-700nm)	#25-390	€101,97 Volume Pricing	1 In Stock
20.00	-	0.50	VIS-EXT (350-700nm)	#28-564	€108,15 Volume Pricing	5 In Stock

20.00	-	1.00	VIS-EXT (350-700nm)	#28-565	€108,15 Volume Pricing	4 In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#28-566	€108,15 Volume Pricing	1 In Stock
20.00	-	3.00	VIS-EXT (350-700nm)	#28-572	€108,15 Volume Pricing	10 In Stock
20.00	-	0.50	VIS-NIR (400-1000nm)	#20-797	€108,15 Volume Pricing	2 In Stock
20.00	-	1.00	VIS-NIR (400-1000nm)	#20-798	€108,15 Volume Pricing	1 In Stock
20.00	-	2.00	VIS-NIR (400-1000nm)	#36-581	€108,15 Volume Pricing	8 In Stock
20.00	-	3.00	VIS-NIR (400-1000nm)	#25-400	€108,15 Volume Pricing	3 In Stock
20.00	-	0.50	NIR I (600-1050nm)	#20-873	€108,15 Volume Pricing	3 In Stock
20.00	-	1.00	NIR I (600-1050nm)	#20-874	€108,15 Volume Pricing	5 In Stock
20.00	-	2.00	NIR I (600-1050nm)	#36-498	€108,15 Volume Pricing	17 In Stock
20.00	-	0.50	NIR II (750-1550nm)	#20-941	€108,15 Volume Pricing	9 In Stock
20.00	-	1.00	NIR II (750-1550nm)	#20-945	€108,15 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR II (750-1550nm)	#36-573	€108,15 Volume Pricing	1 In Stock
20.00	-	3.00	NIR I (600-1050nm)	#25-410	€108,15 Volume Pricing	5 In Stock

20.00	-	3.00	NIR II (750-1550nm)	#25-420	€108,15 Volume Pricing	3 In Stock
20.00	-	0.50	BBAR (1650-3000nm)	#21-005	€124,63 Volume Pricing	6 In Stock
20.00	-	1.00	BBAR (1650-3000nm)	#21-006	€124,63 Volume Pricing	10 In Stock
20.00	-	2.00	BBAR (1650-3000nm)	#15-994	€124,63 Volume Pricing	20+ In Stock
20.00	-	3.00	BBAR (1650-3000nm)	#25-430	€124,63 Volume Pricing	2 In Stock
20.00	-	0.50	BBAR (2000-5000nm)	#21-022	€124,63 Volume Pricing	Contact Us
20.00	-	1.00	BBAR (2000-5000nm)	#21-023	€124,63 Volume Pricing	20+ In Stock
20.00	-	2.00	BBAR (2000-5000nm)	#16-007	€124,63 Volume Pricing	13 In Stock
20.00	-	3.00	BBAR (2000-5000nm)	#25-440	€124,63 Volume Pricing	4 In Stock
22.00	-	1.00	Uncoated	#43-634	€84,46 Volume Pricing	20+ In Stock
23.00	-	1.50	Uncoated	#23-290	€84,46 Volume Pricing	20+ In Stock
23.75	-	1.00	Uncoated	#43-635	€84,46 Volume Pricing	20+ In Stock
25.00	-	0.20	Uncoated	#71-229	€111,76 Volume Pricing	20+ In Stock
25.00	-	0.50	Uncoated	#17-229	€110,21 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#17-230	€110,21 Volume Pricing	20+ In Stock
25.00	-	2.30	Uncoated	#43-369	€109,70 Volume Pricing	Contact Us

25.00	-	0.50	MgF ₂ (400-700nm)	#20-676	€127,72 Volume Pricing	7 In Stock
25.00	-	1.00	MgF ₂ (400-700nm)	#20-681	€127,72 Volume Pricing	3 In Stock
25.00	-	2.30	MgF ₂ (400-700nm)	#36-460	€127,72 Volume Pricing	3 In Stock
25.00	-	0.50	VIS-EXT (350-700nm)	#28-688	€132,87 Volume Pricing	3 In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#28-689	€132,87 Volume Pricing	14 In Stock
25.00	-	2.30	VIS-EXT (350-700nm)	#28-690	€132,87 Volume Pricing	5 In Stock
25.00	-	0.50	VIS-NIR (400-1000nm)	#20-810	€132,87 Volume Pricing	3 In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#20-815	€132,87 Volume Pricing	15 In Stock
25.00	-	2.30	VIS-NIR (400-1000nm)	#36-582	€132,87 Volume Pricing	4 In Stock
25.00	-	0.50	NIR I (600-1050nm)	#20-880	€132,87 Volume Pricing	13 In Stock
25.00	-	1.00	NIR I (600-1050nm)	#20-886	€132,87 Volume Pricing	4 In Stock
25.00	-	2.30	NIR I (600-1050nm)	#36-550	€132,87 Volume Pricing	3 In Stock
25.00	-	0.50	NIR II (750-1550nm)	#20-951	€132,87 Volume Pricing	5 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#20-955	€132,87 Volume Pricing	20+ In Stock

25.00	-	2.30	NIR II (750- 1550nm)	#36-576	€132,87 Volume Pricing	20+ In Stock
25.00	-	0.50	BBAR (1650- 3000nm)	#21-007	€156,56 Volume Pricing	8 In Stock
25.00	-	1.00	BBAR (1650- 3000nm)	#21-008	€156,56 Volume Pricing	15 In Stock
25.00	-	2.30	BBAR (1650- 3000nm)	#15-995	€156,56 Volume Pricing	9 In Stock
25.00	-	0.50	BBAR (2000- 5000nm)	#21-024	€156,56 Volume Pricing	3 In Stock
25.00	-	1.00	BBAR (2000- 5000nm)	#21-060	€156,56 Volume Pricing	11 In Stock
25.00	-	2.30	BBAR (2000- 5000nm)	#16-008	€156,56 Volume Pricing	17 In Stock
25.40	-	0.20	Uncoated	#71-230	€111,76 Volume Pricing	20+ In Stock
25.40	-	0.50	Uncoated	#17-231	€110,21 Volume Pricing	20+ In Stock
25.40	-	1.00	Uncoated	#17-232	€110,21 Volume Pricing	20+ In Stock
25.40	-	2.25	Uncoated	#43-636	€109,70 Volume Pricing	20+ In Stock
25.40	-	5.00	Uncoated	#25-381	€110,21 Volume Pricing	20+ In Stock
25.40	-	0.50	MgF ₂ (400- 700nm)	#20-689	€127,72 Volume Pricing	1 In Stock
25.40	-	1.00	MgF ₂ (400- 700nm)	#20-690	€127,72 Volume Pricing	4 In Stock
25.40	-	2.30	MgF ₂ (400- 700nm)	#39-233	€127,72 Volume Pricing	5 In Stock
25.40	-	5.00	MgF ₂ (400- 700nm)	#25-391	€127,72 Volume Pricing	Contact Us

25.40	-	0.50	VIS-EXT (350-700nm)	#28-691	€132,87 Volume Pricing	1 In Stock
25.40	-	1.00	VIS-EXT (350-700nm)	#28-692	€132,87 Volume Pricing	2 In Stock
25.40	-	2.30	VIS-EXT (350-700nm)	#28-693	€132,87 Volume Pricing	5 In Stock
25.40	-	5.00	VIS-EXT (350-700nm)	#28-694	€132,87 Volume Pricing	8 In Stock
25.40	-	0.50	VIS-NIR (400-1000nm)	#20-834	€132,87 Volume Pricing	Contact Us
25.40	-	1.00	VIS-NIR (400-1000nm)	#20-836	€132,87 Volume Pricing	5 In Stock
25.40	-	2.30	VIS-NIR (400-1000nm)	#39-248	€132,87 Volume Pricing	3 In Stock
25.40	-	5.00	VIS-NIR (400-1000nm)	#25-401	€132,87 Volume Pricing	7 In Stock
25.40	-	0.50	NIR I (600-1050nm)	#20-901	€132,87 Volume Pricing	7 In Stock
25.40	-	1.00	NIR I (600-1050nm)	#20-903	€132,87 Volume Pricing	Contact Us
25.40	-	2.30	NIR I (600-1050nm)	#39-254	€132,87 Volume Pricing	9 In Stock
25.40	-	5.00	NIR I (600-1050nm)	#25-411	€132,87 Volume Pricing	5 In Stock
25.40	-	0.50	NIR II (750-1550nm)	#20-963	€132,87 Volume Pricing	5 In Stock
25.40	-	1.00	NIR II (750-1550nm)	#20-971	€132,87 Volume Pricing	11 In Stock

25.40	-	2.30	NIR II (750-1550nm)	#39-264	€132,87 Volume Pricing	10 In Stock
25.40	-	5.00	NIR II (750-1550nm)	#25-421	€132,87 Volume Pricing	3 In Stock
25.40	-	0.50	BBAR (1650-3000nm)	#21-009	€156,56 Volume Pricing	6 In Stock
25.40	-	1.00	BBAR (1650-3000nm)	#21-010	€156,56 Volume Pricing	13 In Stock
25.40	-	2.30	BBAR (1650-3000nm)	#15-996	€156,56 Volume Pricing	Contact Us
25.40	-	5.00	BBAR (1650-3000nm)	#25-431	€156,56 Volume Pricing	Contact Us
25.40	-	0.50	BBAR (2000-5000nm)	#21-061	€156,56 Volume Pricing	9 In Stock
25.40	-	1.00	BBAR (2000-5000nm)	#21-062	€156,56 Volume Pricing	Contact Us
25.40	-	2.30	BBAR (2000-5000nm)	#16-009	€156,56 Volume Pricing	1 In Stock
25.40	-	5.00	BBAR (2000-5000nm)	#25-441	€156,56 Volume Pricing	Contact Us
-	25.40 x 25.40	1.00	Uncoated	#39-230	€129,78 Volume Pricing	20+ In Stock
28.00	-	1.50	Uncoated	#23-291	€146,26 Volume Pricing	20+ In Stock
30.00	-	0.50	Uncoated	#71-231	€140,60 Volume Pricing	16 In Stock
30.00	-	1.00	Uncoated	#48-919	€146,26 Volume Pricing	20+ In Stock
30.00	-	2.00	Uncoated	#25-382	€146,26 Volume Pricing	20+ In Stock
30.00	-	1.00	MgF ₂ (400-700nm)	#39-234	€169,95 Volume Pricing	Contact Us

30.00	-	2.00	MgF ₂ (400-700nm)	#25-392	€169,95 Volume Pricing	Contact Us
30.00	-	1.00	VIS-EXT (350-700nm)	#28-695	€193,64 Volume Pricing	Contact Us
30.00	-	2.00	VIS-EXT (350-700nm)	#28-696	€193,64 Volume Pricing	11 In Stock
30.00	-	1.00	VIS-NIR (400-1000nm)	#37-702	€193,64 Volume Pricing	9 In Stock
30.00	-	2.00	VIS-NIR (400-1000nm)	#25-402	€193,64 Volume Pricing	Contact Us
30.00	-	1.00	NIR I (600-1050nm)	#39-256	€193,64 Volume Pricing	10 In Stock
30.00	-	2.00	NIR I (600-1050nm)	#25-412	€193,64 Volume Pricing	1 In Stock
30.00	-	1.00	NIR II (750-1550nm)	#39-265	€193,13 Volume Pricing	20+ In Stock
30.00	-	2.00	NIR II (750-1550nm)	#25-422	€193,64 Volume Pricing	2 In Stock
30.00	-	1.00	BBAR (1650-3000nm)	#15-997	€210,12 Volume Pricing	13 In Stock
30.00	-	2.00	BBAR (1650-3000nm)	#25-432	€210,12 Volume Pricing	5 In Stock
30.00	-	1.00	BBAR (2000-5000nm)	#16-010	€210,12 Volume Pricing	20+ In Stock
30.00	-	2.00	BBAR (2000-5000nm)	#25-442	€210,12 Volume Pricing	2 In Stock
31.60	-	1.50	Uncoated	#23-292	€146,26 Volume Pricing	20+ In Stock
31.75	-	1.00	Uncoated	#43-637	€146,26 Volume Pricing	17 In Stock

31.75	-	1.00	MgF ₂ (400-700nm)	#39-236	€169,95 Volume Pricing	20+ In Stock
31.75	-	1.00	VIS-EXT (350-700nm)	#28-697	€193,64 Volume Pricing	8 In Stock
31.75	-	1.00	VIS-NIR (400-1000nm)	#39-249	€193,64 Volume Pricing	4 In Stock
31.75	-	1.00	NIR I (600-1050nm)	#39-257	€193,64 Volume Pricing	20+ In Stock
31.75	-	1.00	NIR II (750-1550nm)	#39-266	€193,13 Volume Pricing	5 In Stock
35.00	-	1.00	Uncoated	#48-920	€231,75 Volume Pricing	20+ In Stock
35.00	-	2.20	Uncoated	#23-293	€231,75 Volume Pricing	12 In Stock
35.00	-	1.00	MgF ₂ (400-700nm)	#39-238	€255,44 Volume Pricing	5 In Stock
35.00	-	1.00	VIS-EXT (350-700nm)	#28-698	€279,13 Volume Pricing	3 In Stock
35.00	-	1.00	VIS-NIR (400-1000nm)	#39-250	€279,13 Volume Pricing	20+ In Stock
35.00	-	1.00	NIR I (600-1050nm)	#39-258	€279,13 Volume Pricing	8 In Stock
35.00	-	1.00	NIR II (750-1550nm)	#39-267	€278,62 Volume Pricing	3 In Stock
38.00	-	1.50	Uncoated	#23-294	€264,71 Volume Pricing	20+ In Stock
38.10	-	1.00	Uncoated	#45-568	€264,71 Volume Pricing	20+ In Stock
38.10	-	1.00	MgF ₂ (400-700nm)	#39-242	€295,61 Volume Pricing	Contact Us

38.10	-	1.00	VIS-EXT (350-700nm)	#28-699	€314,15 Volume Pricing	4 In Stock
38.10	-	1.00	VIS-NIR (400-1000nm)	#39-251	€314,15 Volume Pricing	13 In Stock
38.10	-	1.00	NIR I (600-1050nm)	#39-259	€314,15 Volume Pricing	3 In Stock
38.10	-	1.00	NIR II (750-1550nm)	#39-268	€314,15 Volume Pricing	5 In Stock
40.00	-	1.00	Uncoated	#25-383	€292,52 Volume Pricing	20+ In Stock
40.00	-	2.00	Uncoated	#48-921	€292,52 Volume Pricing	20+ In Stock
40.00	-	1.00	MgF ₂ (400-700nm)	#25-393	€322,39 Volume Pricing	3 In Stock
40.00	-	2.00	MgF ₂ (400-700nm)	#39-243	€322,39 Volume Pricing	4 In Stock
40.00	-	2.00	VIS-EXT (350-700nm)	#28-703	€345,05 Volume Pricing	16 In Stock
40.00	-	1.00	VIS-EXT (350-700nm)	#28-702	€345,05 Volume Pricing	3 In Stock
40.00	-	1.00	VIS-NIR (400-1000nm)	#25-403	€345,05 Volume Pricing	16 In Stock
40.00	-	2.00	VIS-NIR (400-1000nm)	#37-703	€345,05 Volume Pricing	13 In Stock
40.00	-	1.00	NIR I (600-1050nm)	#25-413	€345,05 Volume Pricing	5 In Stock
40.00	-	2.00	NIR I (600-1050nm)	#39-260	€345,05 Volume Pricing	20+ In Stock
40.00	-	1.00	NIR II (750-1550nm)	#25-423	€345,05 Volume Pricing	4 In Stock

40.00	-	2.00	NIR II (750-1550nm)	#39-269	€344,54 Volume Pricing	5 In Stock
40.00	-	1.00	BBAR (1650-3000nm)	#25-433	€361,53 Volume Pricing	4 In Stock
40.00	-	2.00	BBAR (1650-3000nm)	#15-998	€361,53 Volume Pricing	4 In Stock
40.00	-	1.00	BBAR (2000-5000nm)	#25-443	€361,53 Volume Pricing	5 In Stock
40.00	-	2.00	BBAR (2000-5000nm)	#16-011	€361,53 Volume Pricing	9 In Stock
40.20	-	1.50	Uncoated	#23-295	€292,52 Volume Pricing	20+ In Stock
43.20	-	1.50	Uncoated	#23-296	€328,57 Volume Pricing	Contact Us
50.00	-	1.00	Uncoated	#25-384	€435,69 Volume Pricing	14 In Stock
50.00	-	1.00	MgF ₂ (400-700nm)	#25-394	€474,83 Volume Pricing	Contact Us
50.00	-	1.00	VIS-EXT (350-700nm)	#28-704	€488,22 Volume Pricing	5 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#25-404	€488,22 Volume Pricing	1 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#25-414	€488,22 Volume Pricing	3 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#25-424	€488,22 Volume Pricing	2 In Stock
50.00	-	1.00	BBAR (1650-3000nm)	#25-434	€516,03 Volume Pricing	4 In Stock
50.00	-	1.00	BBAR (2000-5000nm)	#25-444	€516,03 Volume Pricing	Contact Us

50.80	-	0.50	Uncoated	#71-233	€435,69 Volume Pricing	8 In Stock
50.80	-	1.00	Uncoated	#25-385	€435,69 Volume Pricing	20+ In Stock
50.80	-	3.18	Uncoated	#45-817	€435,69 Volume Pricing	20+ In Stock
50.80	-	1.00	MgF ₂ (400-700nm)	#25-395	€474,83 Volume Pricing	Contact Us
50.80	-	3.18	MgF ₂ (400-700nm)	#39-245	€474,83 Volume Pricing	6 In Stock
50.80	-	3.18	VIS-EXT (350-700nm)	#28-706	€488,22 Volume Pricing	9 In Stock
50.80	-	1.00	VIS-EXT (350-700nm)	#28-705	€488,22 Volume Pricing	20+ In Stock
50.80	-	1.00	VIS-NIR (400-1000nm)	#25-405	€488,22 Volume Pricing	Contact Us
50.80	-	3.18	VIS-NIR (400-1000nm)	#37-704	€488,22 Volume Pricing	16 In Stock
50.80	-	1.00	NIR I (600-1050nm)	#25-415	€488,22 Volume Pricing	4 In Stock
50.80	-	3.18	NIR I (600-1050nm)	#39-261	€488,22 Volume Pricing	11 In Stock
50.80	-	1.00	NIR II (750-1550nm)	#25-425	€488,22 Volume Pricing	4 In Stock
50.80	-	3.18	NIR II (750-1550nm)	#39-270	€487,71 Volume Pricing	10 In Stock
50.80	-	1.00	BBAR (1650-3000nm)	#25-435	€516,03 Volume Pricing	5 In Stock
50.80	-	3.18	BBAR (1650-3000nm)	#15-999	€520,15 Volume Pricing	7 In Stock

50.80	-	1.00	BBAR (2000-5000nm)	#25-445	€516,03 Volume Pricing	1 In Stock
50.80	-	3.18	BBAR (2000-5000nm)	#16-013	€516,03 Volume Pricing	1 In Stock
55.00	-	2.00	Uncoated	#23-297	€504,70 Volume Pricing	20+ In Stock
59.20	-	1.50	Uncoated	#23-298	€560,32 Volume Pricing	20+ In Stock
63.50	-	2.00	Uncoated	#48-922	€595,34 Volume Pricing	20+ In Stock
75.00	-	1.00	Uncoated	#71-234	€921,85 Volume Pricing	5 In Stock
75.00	-	2.00	Uncoated	#47-542	€923,40 Volume Pricing	20+ In Stock
75.00	-	2.00	MgF ₂ (400-700nm)	#18-947	€993,95 Volume Pricing	4 In Stock
75.00	-	2.00	VIS-EXT (350-700nm)	#28-707	€1.017,64 Volume Pricing	2 In Stock
75.00	-	2.00	VIS-NIR (400-1000nm)	#18-948	€1.019,70 Volume Pricing	20+ In Stock
75.00	-	2.00	NIR I (600-1050nm)	#18-949	€1.019,70 Volume Pricing	2 In Stock
75.00	-	2.00	NIR II (750-1550nm)	#18-950	€1.019,70 Volume Pricing	11 In Stock
75.00	-	2.00	BBAR (1650-3000nm)	#18-951	€1.050,60 Volume Pricing	4 In Stock
75.00	-	2.00	BBAR (2000-5000nm)	#18-952	€1.050,60 Volume Pricing	2 In Stock
100.00	-	2.00	Uncoated	#17-233	€1.308,10 Volume Pricing	1 In Stock
100.00	-	2.00	VIS-NIR (400-1000nm)	#24-172	€1.565,60 Volume Pricing	3 In Stock

125.00	-	2.00	Uncoated	#19-507	€1.617,10 Volume Pricing	5 In Stock
125.00	-	2.00	VIS-NIR (400-1000nm)	#24-173	€1.987,90 Volume Pricing	8 In Stock
150.00	-	3.00	Uncoated	#19-508	€2.121,80 Volume Pricing	7 In Stock
150.00	-	3.00	VIS-NIR (400-1000nm)	#24-174	€2.575,00 Volume Pricing	1 In Stock

[#75-137 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	5 x 5	1.00	Uncoated		€41,20 Volume Pricing	2 In Stock
---	-------	------	----------	--	--	------------

[#75-141 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 10 x 10 1.00 Uncoated

€56,65
[Volume Pricing](#)

14 In Stock

[#75-142 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 20 x 20 2.00 Uncoated

€97,34
[Volume Pricing](#)

1 In Stock

[#75-143 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	25 x 25	2.30	Uncoated		€126,69 Volume Pricing	15 In Stock
---	---------	------	----------	--	---	-------------

[#75-144 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	50 x 50	3.18	Uncoated		€499,55 Volume Pricing	Contact Us
---	---------	------	----------	--	---	------------

[#75-146 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 75 x 75 2.00 Uncoated

€1.055,75
[Volume Pricing](#)

14 In Stock

[#75-147 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 12.5 x 17.5 1.00 Uncoated

€78,28
[Volume Pricing](#)

15 In Stock

[#75-148 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 25 x 35 2.00 Uncoated

€167,89
[Volume Pricing](#)

4 In Stock

[#75-149 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 35 x 50 2.00 Uncoated

€335,78
[Volume Pricing](#)

20+ In Stock

[#75-151 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	5 x 5	1.00	VIS-NIR (400-1000nm)	€67,98 Volume Pricing	9 In Stock
---	-------	------	-------------------------	--	------------

[#75-157 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	10 x 10	1.00	VIS-NIR (400-1000nm)	€77,25 Volume Pricing	9 In Stock
---	---------	------	-------------------------	--	------------

[#75-160 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	20 x 20	2.00	VIS-NIR (400- 1000nm)	€117,42 Volume Pricing	8 In Stock
---	---------	------	-----------------------------	---	------------

[#75-164 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	25 x 25	2.30	VIS-NIR (400- 1000nm)	€126,69 Volume Pricing	6 In Stock
---	---------	------	-----------------------------	---	------------

[#75-166 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	VIS-NIR (400-1000nm)	€561,35 Volume Pricing	9 In Stock
---	---------	------	-------------------------	---	------------

[#75-167 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	75 x 75	2.00	VIS-NIR (400-1000nm)	€1.174,20 Volume Pricing	5 In Stock
---	---------	------	-------------------------	---	------------

[#75-168 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.5 x 17.5	1.00	VIS-NIR (400-1000nm)	€105,06 Volume Pricing	9 In Stock
---	-------------	------	-------------------------	---	------------

[#75-169 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 35	2.00	VIS-NIR (400-1000nm)	€222,48 Volume Pricing	9 In Stock
---	---------	------	-------------------------	---	------------

[#75-170 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	35 x 50	2.00	VIS-NIR (400-1000nm)	€396,55 Volume Pricing	9 In Stock
---	---------	------	-------------------------	---	------------

[#75-171 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	5 x 5	1.00	NIR I (600-1050nm)	€67,98 Volume Pricing	9 In Stock
---	-------	------	-----------------------	--	------------

[#75-172 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	10 x 10	1.00	NIR I (600-1050nm)	€77,25 Volume Pricing	9 In Stock
---	---------	------	-----------------------	--	------------

[#75-175 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	20 x 20	2.00	NIR I (600-1050nm)	€117,42 Volume Pricing	9 In Stock
---	---------	------	-----------------------	---	------------

[#75-177 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 25	2.30	NIR I (600-1050nm)	€126,69 Volume Pricing	8 In Stock
---	---------	------	-----------------------	--	------------

[#75-181 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	NIR I (600-1050nm)	€561,35 Volume Pricing	9 In Stock
---	---------	------	-----------------------	--	------------

[#75-183 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	75 x 75	2.00	NIR I (600-1050nm)		€1.174,20 Volume Pricing	5 In Stock
---	---------	------	-----------------------	--	---	------------

[#75-184 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.5 x 17.5	1.00	NIR I (600-1050nm)		€105,06 Volume Pricing	9 In Stock
---	-------------	------	-----------------------	--	---	------------

[#75-185 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 25 x 35 2.00 NIR I
(600-
1050nm)

€222,48
[Volume Pricing](#)

9 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands
Phone: 1-800-363-1992 : [#75-188 New](#)
www.edmundoptics.com



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 35 x 50 2.00 NIR I
(600-
1050nm)

€396,55
[Volume Pricing](#)

9 In Stock