

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Float Glass](#)
**TECHSPEC® C-Mounted First Surface Mirror**


- Ideal for Precision Alignment
- 35 x 35mm Mirror Dimensions
- 50mm H x 38mm W x 38mm D Housing Dimensions
- [Mirror](#) and [Housing](#) Available Separately

## Common Specifications

### General

Type of Optics:	First Surface Mirror
-----------------	----------------------

### Physical & Mechanical Properties

Dimensions (mm):	38 x 38 x 50
------------------	--------------

Dimensional Tolerance (mm):	±0.25
-----------------------------	-------

Edges:	Ground
--------	--------

Extension Length (mm):	38.0
------------------------	------

### Optical Properties

Surface Flatness (P-V):	4 - 6λ
-------------------------	--------

Substrate:	Float Glass
------------	-------------


Surface Quality:	60-40
------------------	-------

Coating Type:	Metal
---------------	-------

### Threading & Mounting

Thread Type:	C-Mount (1" x 32 TPI)
--------------	-----------------------

Technical Information

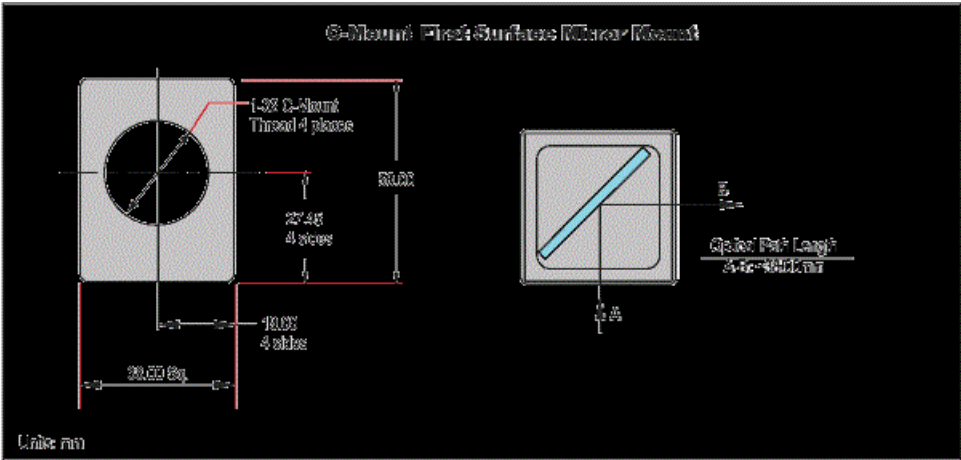

# Products

Surface Flatness (P-V)	Dimensions (mm)	Coating Specification	Coating	Stock Number	Price	Buy
4 - 6λ	38 x 38 x 50	R <sub>avg</sub> >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	<a href="#">#54-825</a>	€313,12 <a href="#">Volume Pricing</a>	8 In Stock
4 - 6λ	38 x 38 x 50	R <sub>avg</sub> >96% @ 700 - 2000nm R <sub>avg</sub> >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	<a href="#">#36-153</a>	€314,15 <a href="#">Volume Pricing</a>	1 In Stock
4 - 6λ	38 x 38 x 50	R <sub>avg</sub> >98% @ 450 - 2000nm R <sub>avg</sub> >98% @ 2000 - 10,000nm	Protected Silver (450-10000nm)	<a href="#">#36-154</a>	€314,15 <a href="#">Volume Pricing</a>	5 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands  
Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)