

[All Products](#) / [Imaging Lenses](#) / [Zoom & Variable Magnification Lenses](#) / [High Magnification Long Working Distance Zoom Lenses](#)

InfiniProbe™ Microscopes

See More by [Infinity Photo-Optical Company](#)



- Available in Standard and Right Angle Versions
- Focuses From Infinity to 32, 28, and 18mm Respectively
- Max. Sensor Format 2/3"
- Magnification From 2.5X to 8.0X
- Direct Video C-Mount Coupling

Common Specifications



Sensor



Maximum Sensor Format: 2/3"

Threading & Mounting


Mount: C-Mount

Technical Information

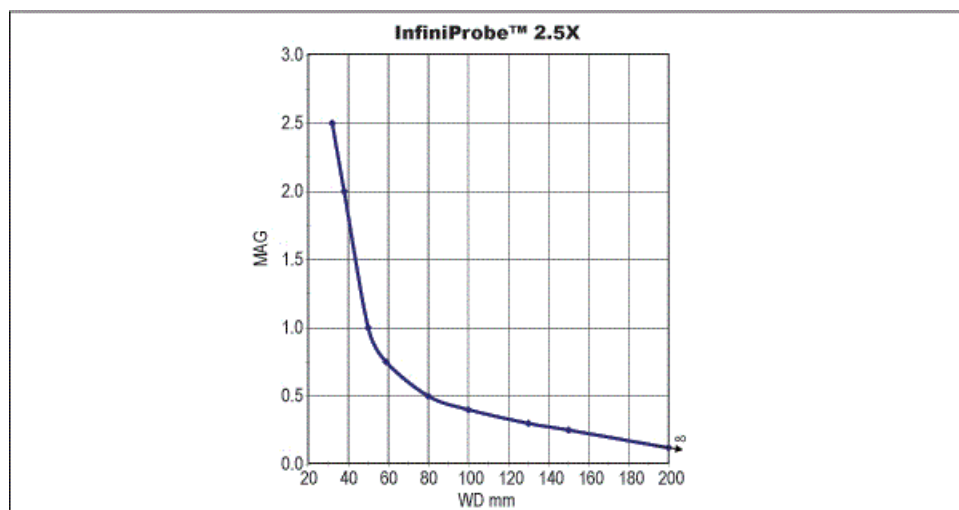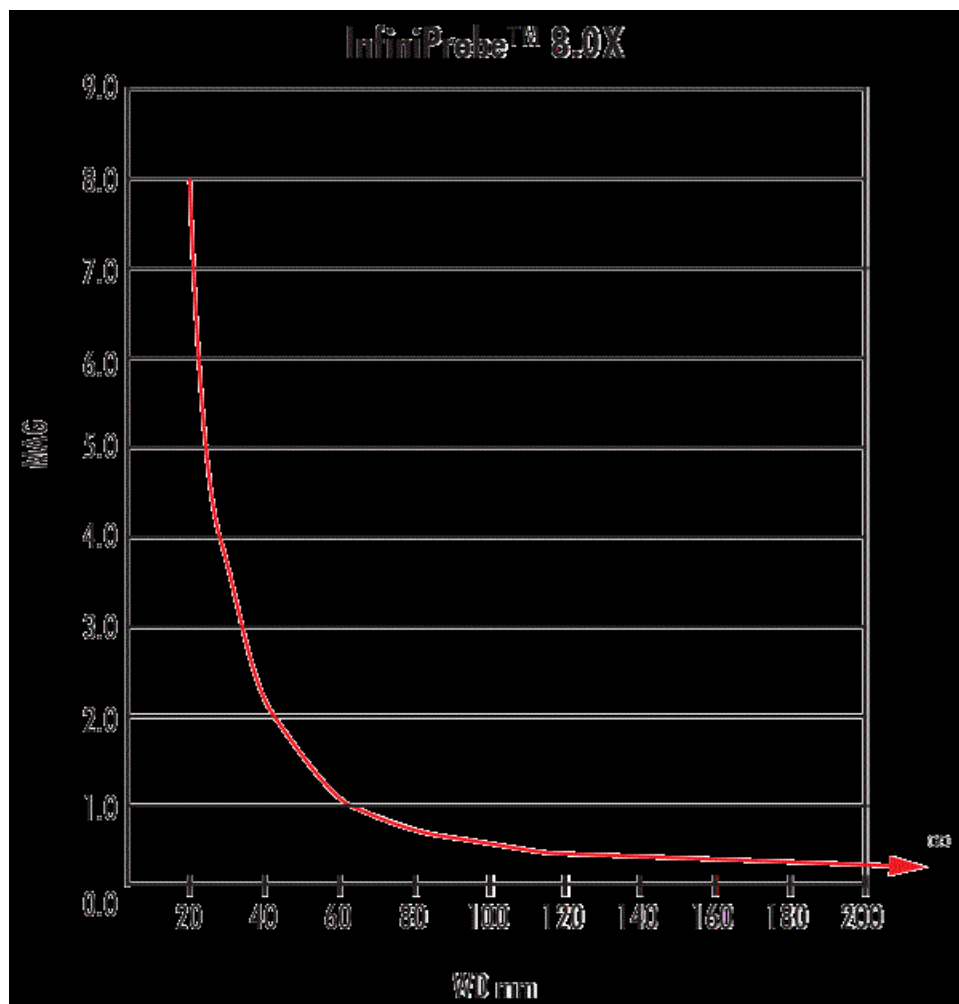

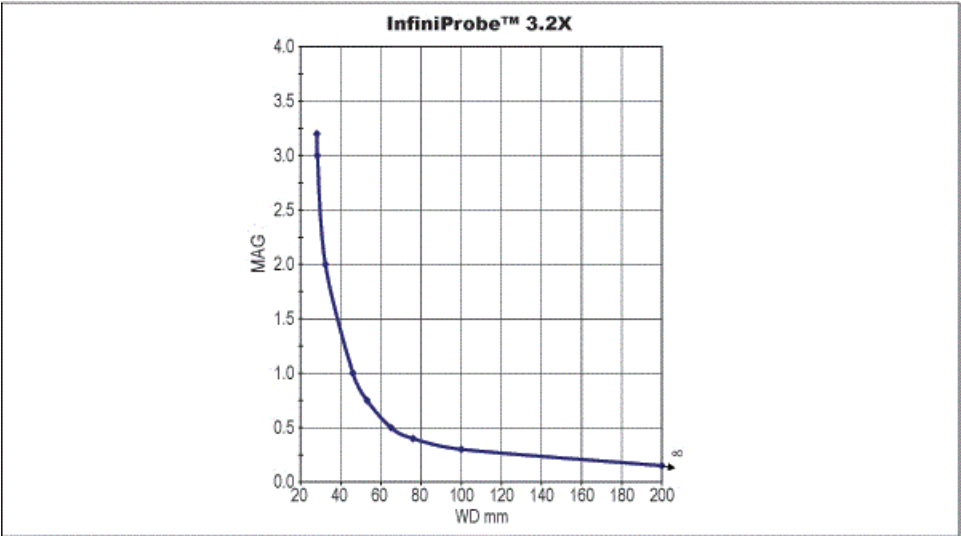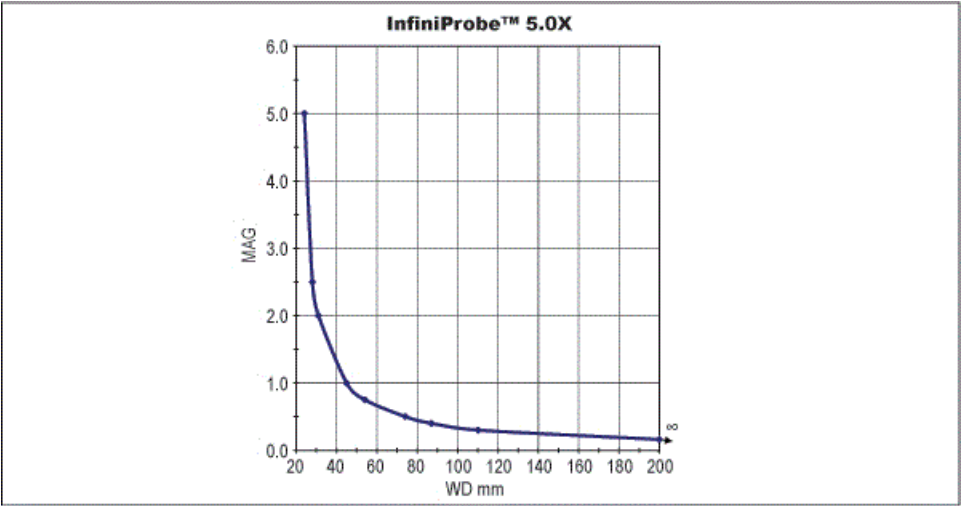

InfiniProbe™ PMAG vs WD Curves

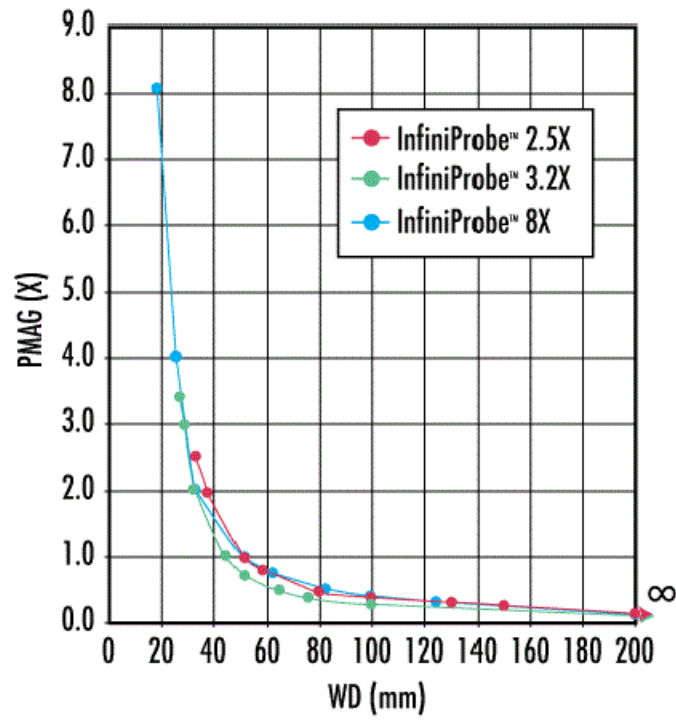

Products

Title	Stock Number	Price	Buy
InfiniProbe S-25 Video Microscope (0-2.5X)	#58-806	€2.135,00	Contact Us
InfiniProbe S-32 Video Microscope (0-3.2X)	#58-807	€2.390,00	Contact Us
InfiniProbe S-80 Video Microscope (0-8.0X)	#58-809	€3.175,00	1 In Stock
InfiniProbe S-25 Right Angle Video Microscope (0-2.5X)	#58-810	€2.670,00	Contact Us
InfiniProbe S-32 Right Angle Video Microscope (0-3.2X)	#58-811	€2.930,00	2 In Stock
InfiniProbe S-80 Right Angle Video Microscope (0-8.0X)	#58-813	€3.690,00	Contact Us



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands

Phone: 1-800-363-1992 :

www.edmundoptics.com