

[All Products](#) / [Imaging Lenses](#) / [Fixed Focal Length Lenses](#)

## **TECHSPEC® LF Series Fixed Focal Length Lenses**




- Full Frame (35mm), F-Mount Lens
- 29 MegaPixels, 5µm Pixel Size Sensors
- F-Mount Large Format (LF) Lens for Factory Automation
- 28mm to 100mm Focal Length

# Common Specifications


General			
Series: LF Series		Imaging Lens Type: Lens for Large Format Sensors	
Physical & Mechanical Properties			
Iris Option: Variable			
Optical Properties			
Maximum Image Circle (mm): 43.30			
Coating: λ/4 MgF2		Coating Specification: λ/4 MgF2	
Sensor			
Maximum Sensor Format: 35mm (43.3mm Image Circle)		Pixel Size (μm): 5.00	
Threading & Mounting			
Mount: F-Mount			
Environmental & Durability Factors			
Storage Temperature (°C):		<a href="#">-20 to +60</a>	

## Technical Information

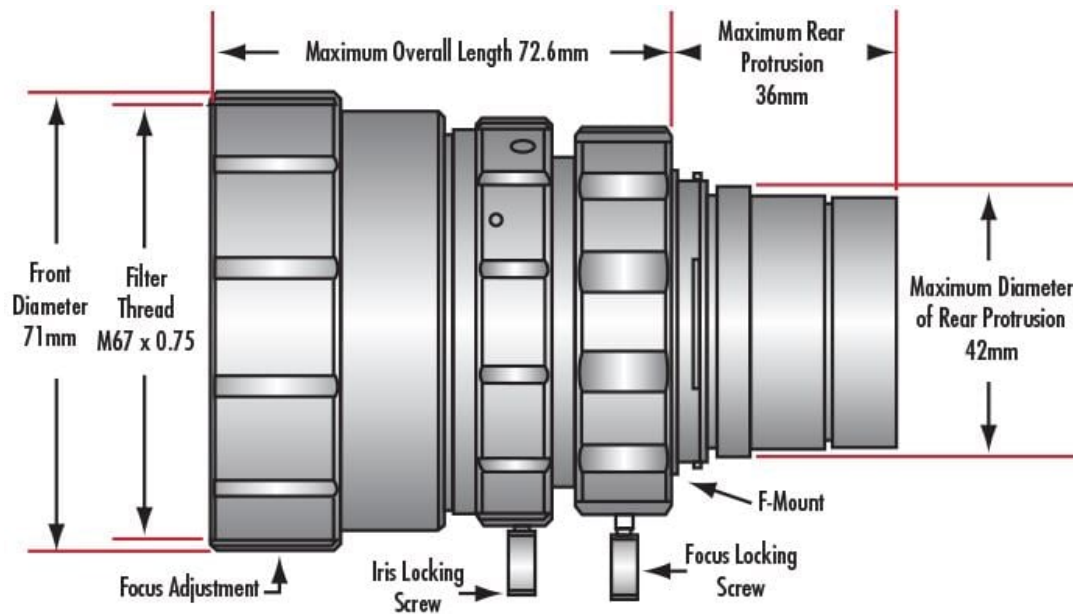


28mm Focal Length

### 50mm Focal Length Large Format Lens

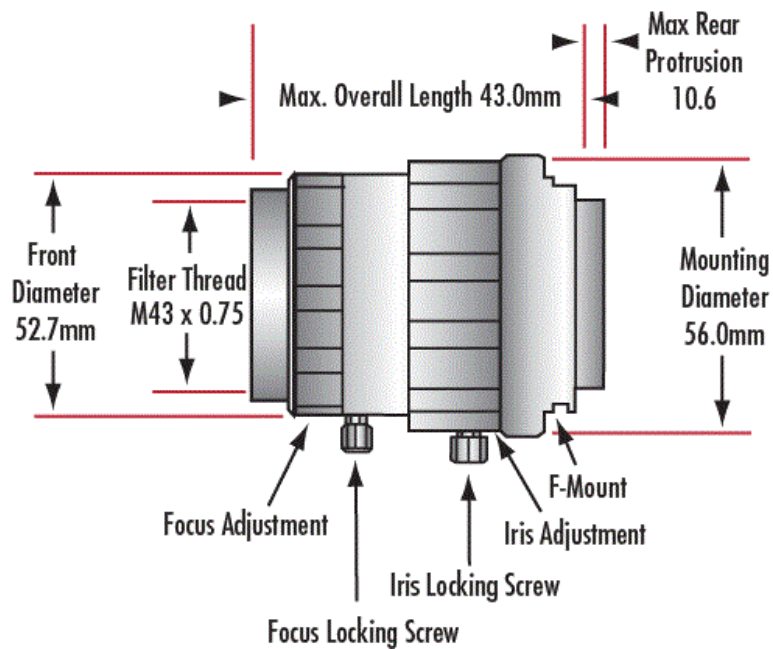

## 100mm Focal Length Large Format Lens

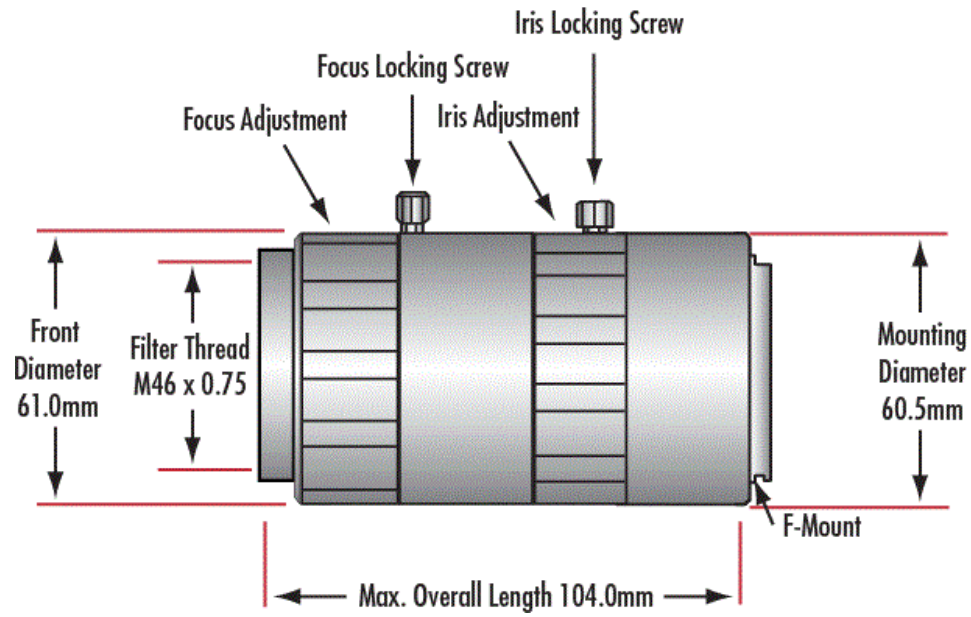

Products

FL (mm)	Max. Sensor Format	Aperture (f/#)	WD (mm)	Optimized Working Distance (mm)	Mount	Stock Number	Price	Buy
28.00	35mm (43.3mm Image Circle)	f/2.8 - f/22	400 - ∞	400 - 700	F- Mount	<a href="#">#85-199</a>	€1.965,00	20+ In Stock
28.00	35mm (43.3mm Image Circle)	f/2.8 - f/22	700 - ∞	-	F- Mount	<a href="#">#85-200</a>	€1.965,00	7 In Stock
50.00	35mm (43.3mm Image Circle)	f/2 - f/22	500 - ∞	-	F- Mount	<a href="#">#85-203</a>	€1.040,00	20+ In Stock
100.00	35mm (43.3mm Image Circle)	f/2.8 - f/22	500 - ∞	-	F- Mount	<a href="#">#85-204</a>	€1.530,00	13 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands  
Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)