

[All Products](#) / [Lights and Illumination](#) / [Spectroscopy Lighting](#)

Fiber Coupled LEDs



- Center Wavelengths from 375 - 1050nm
- Integrated Heat Sink for Thermal Management
- Continuous, TTL, or Analog Modulation Operation

Common Specifications

General

Operating Lifetime (hours): ~10,000

Contents of Kit:



- 1 x Mounted LED
- 1 x LED Driver
- 1 x SMA Cable for Modulation
- 1 x $\varnothing 600\mu\text{m}$, 1m Length, 0.22NA, MM Patchcord

Note: 5V DC Power Supply sold separately

Hardware & Interface Connectivity

Connector: SMA

Technical Information

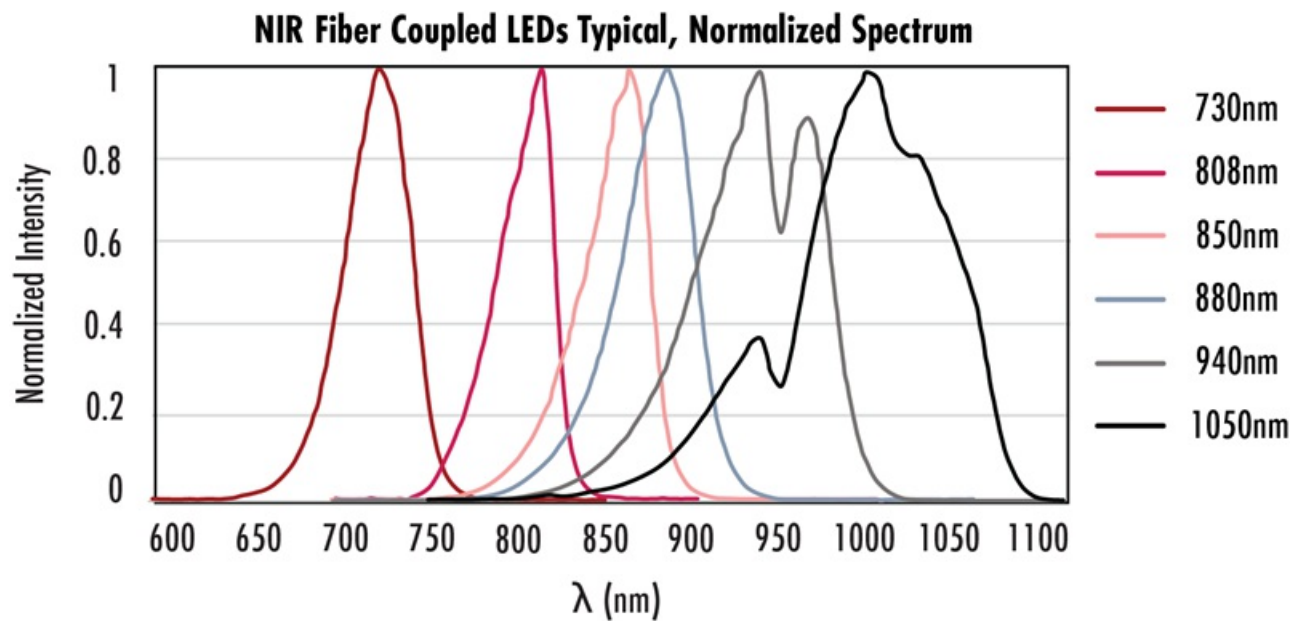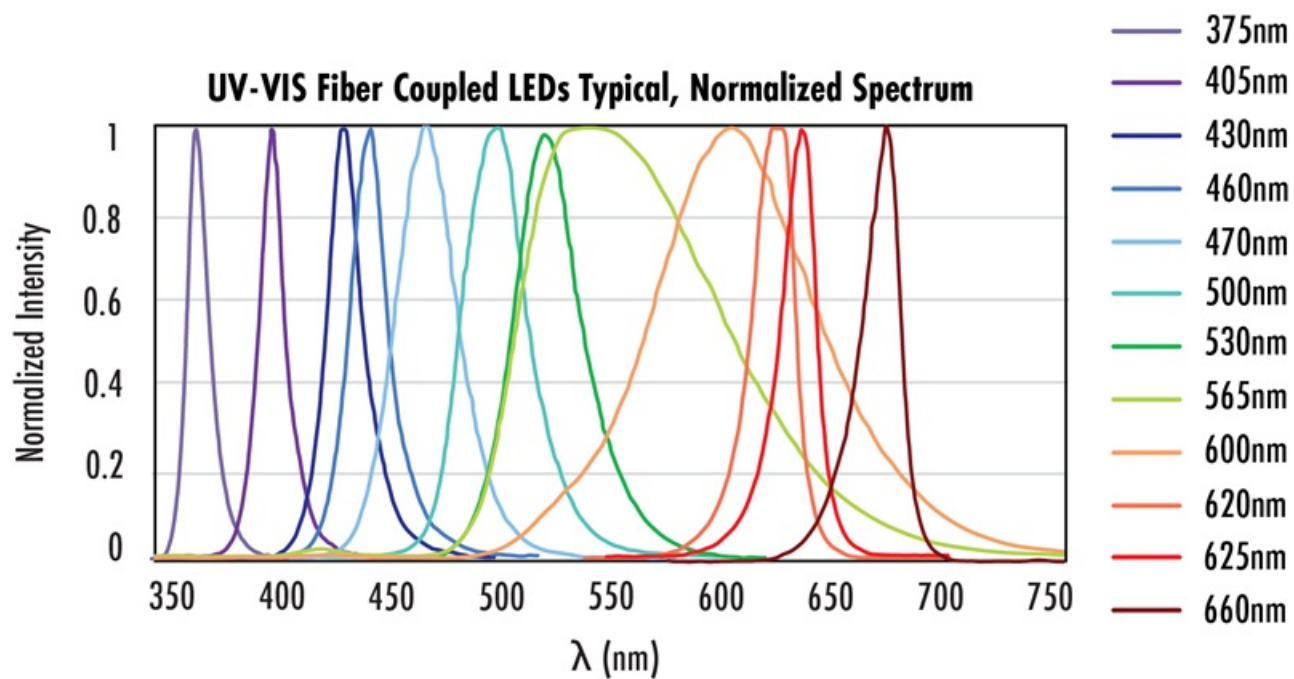

Products

Wavelength (nm)	Output Power (mW)	Current (mA)	Connector	Stock Number	Price	Buy
375.00	10	1400	SMA	#23-727	€850,00	1 In Stock
405.00	8	1400	SMA	#23-728	€850,00	1 In Stock
430.00	1.5	500	SMA	#23-729	€850,00	1 In Stock
460.00	8	1000	SMA	#23-730	€850,00	1 In Stock
470.00	8	1000	SMA	#23-731	€850,00	1 In Stock
500.00	3	1000	SMA	#23-732	€850,00	1 In Stock
530.00	5	1000	SMA	#23-733	€850,00	5 In Stock
565.00	5	1000	SMA	#23-734	€850,00	1 In Stock
600.00	3	1000	SMA	#23-735	€850,00	1 In Stock
620.00	6	1000	SMA	#23-736	€850,00	Contact Us
625.00	5	1000	SMA	#23-737	€850,00	1 In Stock
660.00	5	1200	SMA	#23-738	€850,00	1 In Stock
730.00	5	1000	SMA	#23-739	€850,00	1 In Stock
808.00	5	500	SMA	#23-740	€850,00	6 In Stock
850.00	8	1500	SMA	#23-741	€850,00	1 In Stock
880.00	1	1000	SMA	#23-742	€850,00	1 In Stock
940.00	4	1000	SMA	#23-743	€850,00	1 In Stock
1,050.00	4	600	SMA	#23-744	€1.250,00	1 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands
Phone: 1-800-363-1992 :
www.edmundoptics.com